


Ø .375 [9.5] SMALL  
Ø .750 [19] LARGE  
(2) KEYHOLES FOR  
Ø 5/16 [8 MM]  
HARDWARE

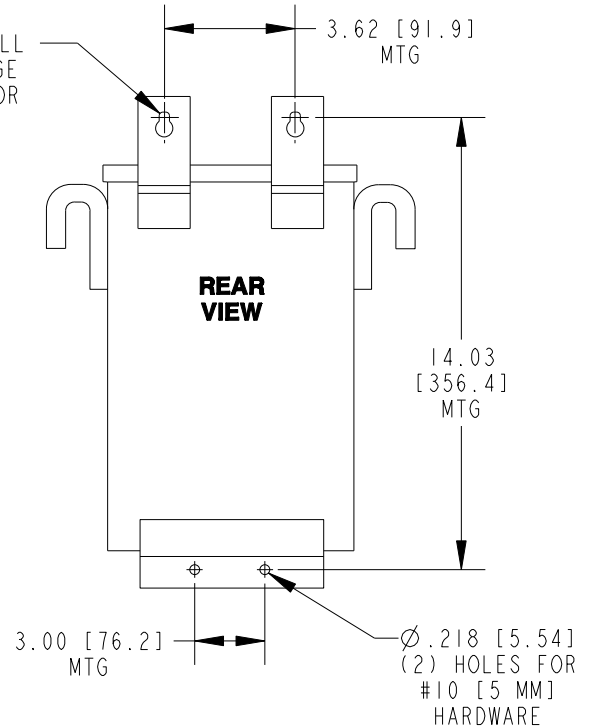

**kVA RATING:**  
**K-FACTOR:**  
**PRI VOLTAGE:**  
**SEC VOLTAGE:**  
**FREQ (Hz):**  
**TEMP RISE:**  
**WINDING MATL:**  
**ES SHIELD:**  
**SOUND LVL (dB):**

**APPROX TOTAL WEIGHT**  
**175 LBS [79 KG]**

**JOB NAME:**

 
**SPEEDI PROP:**

**UNLESS OTHERWISE SPECIFIED  
ALL DIMENSIONS ARE INCH [MM]**



**GE Energy**

**THIRD ANGLE PROJECTION**



**DRY TYPE TRANSFORMER OUTLINE DRAWING  
TYPE QMS, 3-PHASE  
(ENCLOSED INDOOR/OUTDOOR UNIT)**

**CAD DRAWING: 303B924AAP009**

**SHEET 1 OF 1**

**CATALOG #**

**REV 14**