

K Factor Transformer

Catalog Number TYPE QLFK

9T03B7246

500 KVA 60 HZ 3 PH 4.80 % IMP


40 C AMBIENT 115 C RISE 220C SYSTEM FH4G

PRIMARY 480 (H)


SECONDARY 208Y/120 (X)

SERIAL NUMBER 228220

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

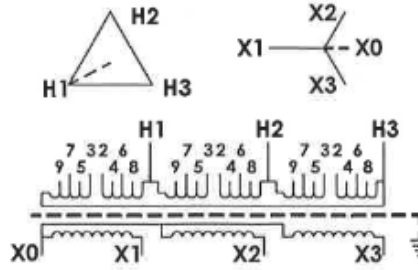

COIL TAP ARRANGEMENT

 

JUMPER CONNECTION

TAP	VOLTS
2 TO 3	500
2 TO 5	490
3 TO 4	480
4 TO 5	470
5 TO 6	460
4 TO 7	440
6 TO 7	430



LISTED
POWER

TRANSFORMER 641H

TYPE 1 ENCLOSURE

SUITABLE FOR NONSINUSOIDAL CURRENT LOAD WITH K-FACTOR NOT TO EXCEED 13

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION IN-7700

COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

NET WGT 4200 LB

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

MEETS 10 CFR 431 (2016) EFFICIENCY CALCULATED AT K-1 RATING

GE CONSUMER AND INDUSTRIAL

NEMA CLASS AA DRY TYPE TRANSFORMER

MADE IN USA