

Transformer

by **ABB**

Catalog Number

TYPE QLF3


9T03U7973G31

45kVA 60Hz 3PH 3.86% IMP


40°C AMBIENT 115°C RISE 220°C SYSTEM FH4G

PRIMARY: 480 (H)

SECONDARY: 208Y/120 (X)

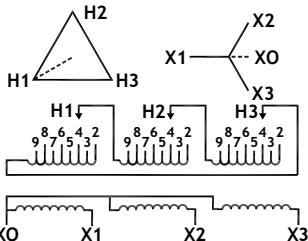

COIL TAP ARRANGEMENT

 

JUMPER CONNECTION

TAP	VOLTS
2	506
3	493
4	480
5	468
6	455
7	442
8	433



LISTED

POWER

TRANSFORMER 641H

TYPE 2 ENCLOSURE, RAINPROOF TYPE 3R ENCLOSURE WHEN PROVIDED WITH SHIELD KIT N75TR3

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION IN-7700

COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

NET WEIGHT 520 lb

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST FOUR INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

MEETS 10 CFR 431 (2016) EFFICIENCY

NEMA CLASS AA DRY TYPE TRANSFORMER

Made in U.S.A.

003121