

# GE Transformer

by ABB



\*1M000000\*

**Catalog Number**

**9T10A1000**


**Type QL**

11.0 KVA    60 HZ    3 PH    2.7 % IMP  
 40 C AMB.    150 C RISE    220 C SYSTEM    IS-19C


**JUMPER CONNECTION TAP VOLTS**

1	504
2	493
3	480
4	468
5	455
6	445
7	432

PRIMARY (H)    480 VOLTS (LINE-LINE)  
 SECONDARY (X)    208 VOLTS (LINE-LINE)  
                           120 VOLTS (LINE-NEUTRAL)

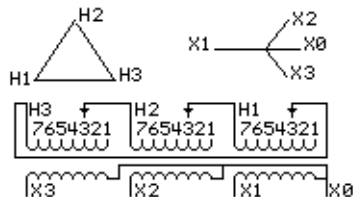

**COIL TAP ARRANGEMENT**

 

**NET WGT**  
 231 LB  
 104.8 Kg  
 90225  
 UX71A

**INSPECTION & FINAL TEST**  
 NP1  
 N238@  
 091922



ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y1071G06

**BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001**

ALUMINUM CONDUCTOR    PRIMARY: 10 KV BIL    SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9. ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.  
 CHECK ADDITIONAL NEC AND LOCAL CODES.

NEMA CLASS AA DRY TYPE TRANSFORMER

**ASSEMBLED IN MEXICO**

**X3 - X2 - X1 - X0**  
**- H3 - H2 - H1**

Note: Standard

Outline: 303B111GEUXP71A

X0

X1

X2

X3

H1

H2

H3

X0

X1

X2

X3

H1

H2

H3



\*2M000000\*



\*3M000000\*