

**GE Transformer**

—  
**by ABB**




**Catalog Number**      **Type QL**  
**9T10A1001G05**

**15.0 KVA    60 HZ    3 PH    3.7 % IMP**  
**40 C AMB.    150 C RISE    220 C SYSTEM    IS-19C**

**PRIMARY (H)    480 VOLTS (LINE-LINE)**  
**SECONDARY (X)    208 VOLTS (LINE-LINE)**  
**120 VOLTS (LINE-NEUTRAL)**

**JUMPER CONNECTION**

TAP	VOLTS
1	504
2	493
3	480
4	468
5	455
6	445
7	432

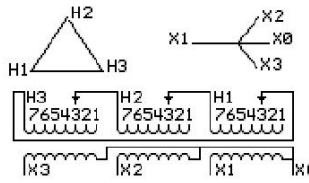


**NET WGT**  
231 LB  
104.8 Kg  
89014  
UX71A

**INSPECTION & FINAL TEST**  
**NOG**  
N139!  
092021



**COIL TAP ARRANGEMENT**

 

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1071G06

ASSEMBLED IN MEXICO

**BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001**  
ALUMINUM CONDUCTOR    PRIMARY: 10 KV BIL    SECONDARY: 10 KV BIL  
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.  
CHECK ADDITIONAL NEC AND LOCAL CODE

X3	H3	X2	H2	X1	H1	X0
-	-	-	-	-	-	-

Note: standard

Outline: 303B111GEUXP71A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

X3 H3 X2 H2 X1 H1 X0  
X3 H3 X2 H2 X1 H1 X0  
X3 H3 X2 H2 X1 H1 X0

