



Transformer

by ABB




1M000000

Catalog Number 9T10A1004G36 **Type** QL


75.0 KVA 60 HZ 3 PH 6.4 % IMP
40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
120 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	TAP VOLTS
1	502
2	491
3	480
4	469
5	455
6	444
7	433

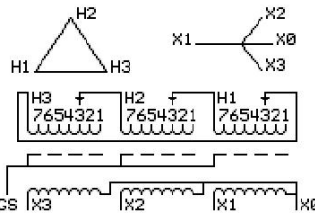

COIL TAP ARRANGEMENT

 

NET WGT
603 LB
273.5 Kg
89043
UX74A

INSPECTION & FINAL TEST
NOG
N139!
092021



LISTED 769G

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

X3	H3	X2	H2	X1	H1
-	-	-	-	-	-


Note: X0 at the bottom

Outline: 303B111GEUXP74A


NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

X3	H3	X2	H2	X1	H1
-	-	-	-	-	-
X3	H3	X2	H2	X1	H1
-	-	-	-	-	-

 

2M000000

 

3M000000

X0