



Transformer

by ABB



1M000000

Catalog Number


Type QL

9T10A1005

112.5 KVA 60 HZ 3 PH 3.5 % IMP
 40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

JUMPER CONNECTION TAP VOLTS

1-2	505
2-3	490
3-4	480
4-5	470
5-6	455
6-7	445
7-8	430

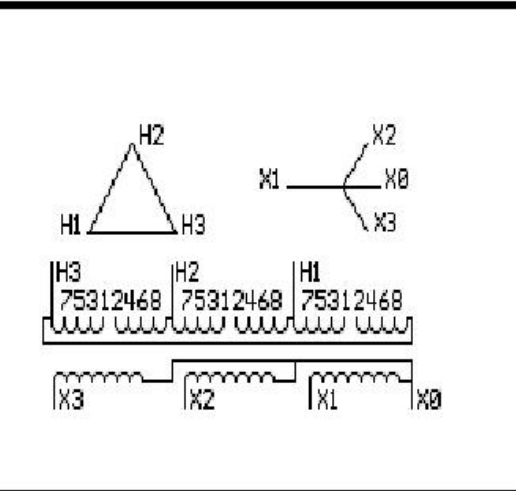

NET WGT
 703 LB
 318.9 Kg
 87825




LISTED 769G

DY05A
NOG
050521

INSPECTION & FINAL TEST
N119!

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

COIL TAP ARRANGEMENT

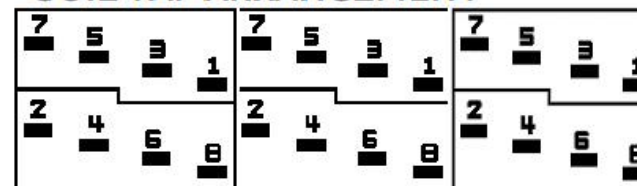

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B111GEDYP05A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000