



Transformer

by ABB



 

1M000000

Catalog Number 9T10A1005G99
Type QL

112.5 KVA **60 HZ** **3 PH** **3.5 % IMP**
40 C AMB. **150 C RISE** **220 C SYSTEM** **IS-19C**

PRIMARY (H) **480 VOLTS (LINE-LINE)**
SECONDARY (X) **208 VOLTS (LINE-LINE)**
 120 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	TAP VOLTS
1-2	505
2-3	490
3-4	480
4-5	470
5-6	455
6-7	445
7-8	430

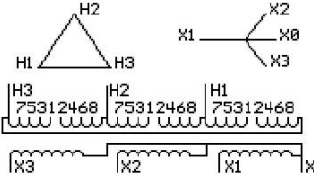

NET WGT
703 LB
318.9 Kg
89056
DY05A

INSPECTION & FINAL TEST
NOG
N137!
091021



X3 - X2 - X1 - - - H3 - H2 - H1
 X3 - X2 - X1 - - - H3 - H2 - H1
 X0

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

X3 - X2 - X1 - - -
- H3 - H2 - H1
Note: X0 at the bottom

Outline: 303B111GEDYP05A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000