




—
by ABB



Catalog Number **Type QL**
9T10A1007G03
 225.0 KVA 60 HZ 3 PH 5.4 % IMP
 40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

JUMPER CONNECTION

TAP	VOLTS
1-2	506
2-3	493
3-4	480
4-5	468
5-6	455
6-7	442
7-8	430

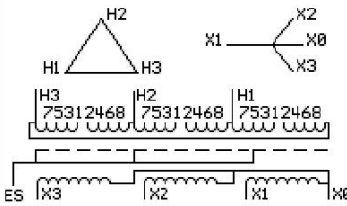


NET WGT **INSPECTION & FINAL TEST**
 1450 LB 657.7 Kg
 89073 **NOG**
 DY77A N139!
 092021



PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

 COIL TAP ARRANGEMENT



ELECTROSTATIC GROUND SHIELD IN EACH PHASE

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009
 ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B112GEDYP77A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

