



—  
by ABB



\*1M000000\*


**Catalog Number**      **Type QL**  
**9T10A1008G03**

300.0 KVA    60 HZ    3 PH    5.5 % IMP  
40 C AMB.    150 C RISE    220 C SYSTEM    IS-19C


PRIMARY (H)      480 VOLTS (LINE-LINE)  
SECONDARY (X)    208 VOLTS (LINE-LINE)  
                         120 VOLTS (LINE-NEUTRAL)

**JUMPER CONNECTION**

TAP	VOLTS
1-2	507
2-3	494
3-4	480
4-5	467
5-6	454
6-7	447
7-8	434

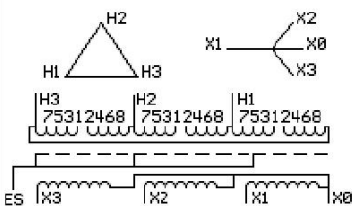

**COIL TAP ARRANGEMENT**

 

**NET WGT**      **INSPECTION & FINAL TEST**  
1670 LB  
757.5 Kg      **NOG**  
89082          **N139!**  
DY78A          **092021**



ELECTROSTATIC GROUND SHIELD IN EACH PHASE

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

ASSEMBLED IN MEXICO

**BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009**  
ALUMINUM CONDUCTOR    PRIMARY: 10 KV BIL                  SECONDARY: 10 KV BIL  
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.  
CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B112GEDYP78A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



\*2M000000\*



\*3M000000\*