



# Transformer



\*1M0000000\*

Catalog Number

Type QL


**9T10A1037**

**225.0 KVA 60 HZ 3 PH 6.2 % IMP**


40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)

SECONDARY (X) 208 VOLTS (LINE-LINE)

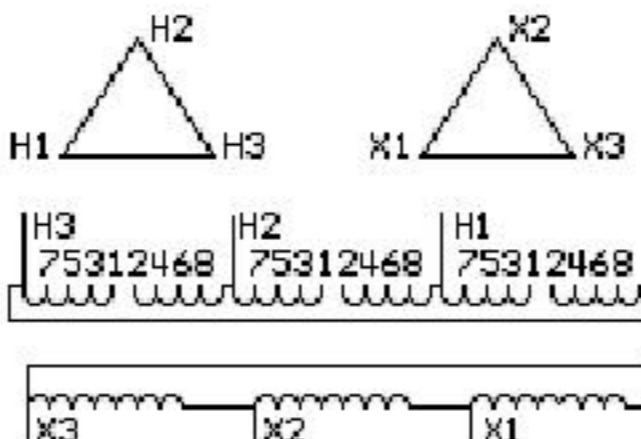

### COIL TAP ARRANGEMENT

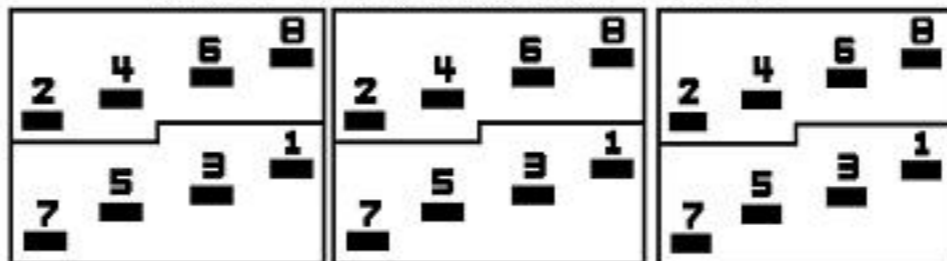

JUMPER CONNECTION	
TAP	VOLTS
1-2	502
2-3	489
3-4	480
4-5	465
5-6	459
6-7	447
7-8	434

NET WGT  
1450 LB  
657.7 Kg

58707  
DY77A

NOG  
121415

INSPECTION  
&  
FINAL TEST  
N551!



ENCLOSURE TYPE 2 (IP20) OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

Outline:

ALUMINUM CONDUCTOR

PRIMARY: 10 KV BIL


SECONDARY: 10 KV BIL

303B112GEDYP77A

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE



\*2M0000000\*

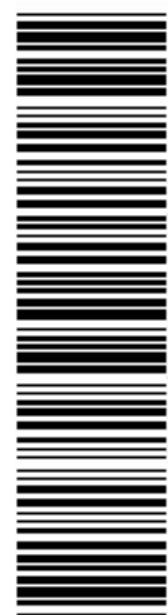

\*3M0000000\*