



Transformer

by ABB



1M000000


Catalog Number 9T10A1051G03 **Type** QL

15.0 KVA **60 HZ** **3 PH** **4.3 % IMP**
40 C AMB. **150 C RISE** **220 C SYSTEM** **IS-19C**


PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 240 VOLTS (LINE-LINE)
139 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION

TAP	VOLTS
1	504
2	491
3	480
4	468
5	456
6	443
7	432

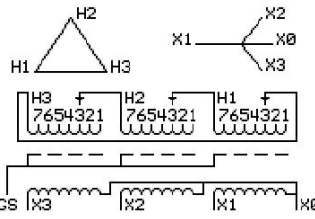

COIL TAP ARRANGEMENT

 

NET WGT
231 LB
104.8 Kg

INSPECTION & FINAL TEST
NOG
N139!
092021

89117
UX71A



LISTED 769G

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1071G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.

CHECK ADDITIONAL NEC AND LOCAL CODE

X3	H3	X2	H2	X1	H1	X0
-	-	-	-	-	-	-

Note: standard

Outline: 303B111GEUXP71A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

X0
X1
H1
X2
H2
X3
H3



2M000000



3M000000