



Transformer

by ABB




1M000000

Catalog Number 9T10A1058 **Type** QL


300.0 KVA 60 HZ 3 PH 5.4 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 240 VOLTS (LINE-LINE)
139 VOLTS (LINE-NEUTRAL)

| JUMPER CONNECTION | |
|-------------------|-------|
| TAP | VOLTS |
| 1-2 | 501 |
| 2-3 | 495 |
| 3-4 | 480 |
| 4-5 | 468 |
| 5-6 | 455 |
| 6-7 | 442 |
| 7-8 | 429 |

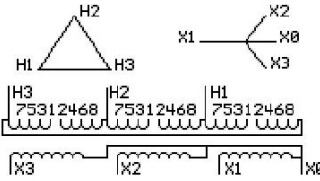

COIL TAP ARRANGEMENT

 

| | |
|---------------------------------------|--|
| NET WGT 1670 LB 757.5 Kg | INSPECTION & FINAL TEST NOG N139! 092021 |
| 89121 DY78A | |



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009
 ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B112GEDYP78A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000