



Transformer

by ABB




1M000000

Catalog Number **Type QL**
9T10A1104G05


75.0 KVA 60 HZ 3 PH 5.7 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 480 VOLTS (LINE-LINE)

JUMPER CONNECTION	TAP	VOLTS
1	505	
2	491	
3	480	
4	469	
5	455	
6	445	
7	431	

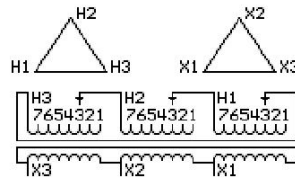

COIL TAP ARRANGEMENT

 

NET WGT
561 LB
254.5 Kg
89155
UY74A

INSPECTION & FINAL TEST
NOG
N137!
091021



X3 H3 X2 H2 X1 H1
- - - - -
X3 H3 X2 H2 X1 H1
- - - - -

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

X3 H3 X2 H2 X1 H1
- - - - -
Note: standard

Outline: 303B111GEUY74A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

