



Transformer

by ABB




1M000000

Catalog Number 9T10A1133 **Type** QL


45.0 KVA 60 HZ 3 PH 5 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 440 VOLTS (LINE-LINE)
254 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	TAP VOLTS
1	505
2	491
3	480
4	467
5	455
6	444
7	432

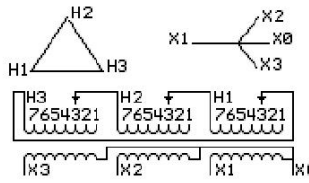

COIL TAP ARRANGEMENT

 

NET WGT
444 LB
201.4 Kg
88751
UX73A

INSPECTION & FINAL TEST
NOG
N137!
091021



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

X3	H3	X2	H2	X1	H1	X0
-	-	-	-	-	-	-

Note: standard

Outline: 303B111GEUXP73A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

X0
X1
H1
X2
H2
X3
H3

