



# Transformer

by ABB




\*1M000000\*

**Catalog Number** 9T10A1144 **Type** QL


75.0 KVA 60 HZ 3 PH 5.1 % IMP  
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 480 VOLTS (LINE-LINE)  
SECONDARY (H) 600 VOLTS (LINE-LINE)  
346 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION TAP	VOLTS
1	505
2	491
3	480
4	469
5	455
6	444
7	433

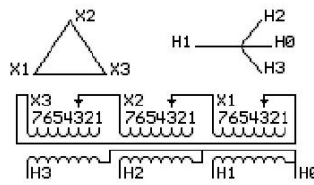

### COIL TAP ARRANGEMENT

 

**NET WGT**  
561 LB  
254.5 Kg  
89172  
UY74A

**INSPECTION & FINAL TEST**  
NOG  
N137!  
091021



LISTED 769G

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

**BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001**  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL  
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.  
CHECK ADDITIONAL NEC AND LOCAL CODE

H3 X3 H2 X2 H1 X1

Note: H0 at the bottom  
Outline: 303B111GEUY74A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

H3 X3 H2 X2 H1 X1  
- - - - -  
\*2M000000\*

H3 X3 H2 X2 H1 X1  
- - - - -  
\*3M000000\*