



# Transformer

by ABB



 

\*1M000000\*

**Catalog Number**      **Type QL**  
**9T10A1174G31**

75.0 KVA    60 HZ    3 PH    5.6 % IMP  
40 C AMB.    115 C RISE    220 C SYSTEM    IS-19C

PRIMARY (H)    480 VOLTS (LINE-LINE)  
SECONDARY (X)    480 VOLTS (LINE-LINE)  
   277 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	TAP VOLTS
1	503
2	492
3	480
4	467
5	456
6	445
7	460

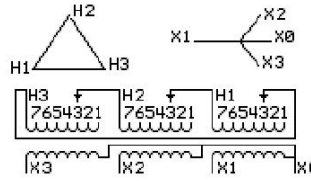

**NET WGT**  
603 LB  
273.5 Kg  
89183  
UX74A

**INSPECTION & FINAL TEST**  
**NOG**  
N139!  
092021



X3	H3	X2	H2	X1	H1	-	-
X3	H3	X2	H2	X1	H1	-	-
X3	H3	X2	H2	X1	H1	-	-

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

**BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001**  
ALUMINUM CONDUCTOR    PRIMARY: 10 KV BIL    SECONDARY: 10 KV BIL  
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.  
CHECK ADDITIONAL NEC AND LOCAL CODE

X3	H3	X2	H2	X1	H1	-	-
-	-	-	-	-	-	-	-

Note: X0 at the bottom

Outline: 303B111GEUXP74A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



\*2M000000\*



\*3M000000\*