




1M000000

Catalog Number **Type QL**
9T10A1174G32


75.0 KVA 60 HZ 3 PH 5.6 % IMP
40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

JUMPER CONNECTION	TAP VOLTS
1	503
2	492
3	480
4	467
5	456
6	445
7	460

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 480 VOLTS (LINE-LINE)
 277 VOLTS (LINE-NEUTRAL)

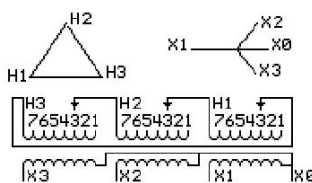

COIL TAP ARRANGEMENT

 

NET WGT
603 LB
273.5 Kg
89184
UX74A

INSPECTION & FINAL TEST
NOG
N139!
092021



X3 H3 X2 H2 X1 H1
X3 H3 X2 H2 X1 H1
X3 H3 X2 H2 X1 H1
X0

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

X3 H3 X2 H2 X1 H1

Note: X0 at the bottom

Outline: 303B111GEUXP74A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

