

Transformer

by ABB



1M000000

Catalog Number
9T10A1177G34


Type QL

225.0 KVA 60 HZ 3 PH 4.5 % IMP
40 C AMB. 115 C RISE 220 C SYSTEM IS-19C


PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 480 VOLTS (LINE-LINE)
277 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION

TAP	VOLTS
1-2	501
2-3	495
3-4	480
4-5	468
5-6	455
6-7	442
7-8	429

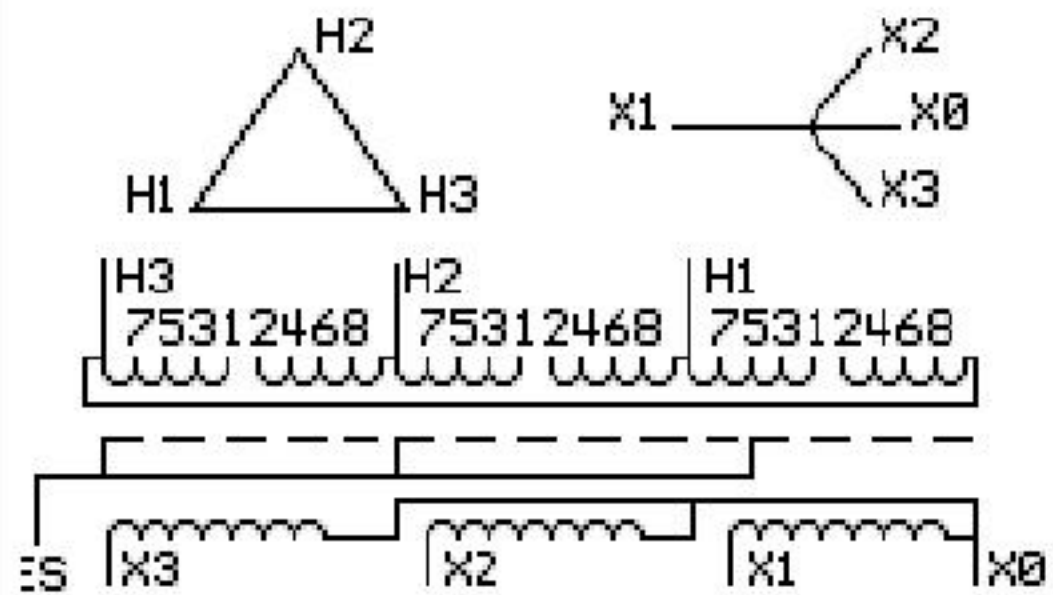

COIL TAP ARRANGEMENT

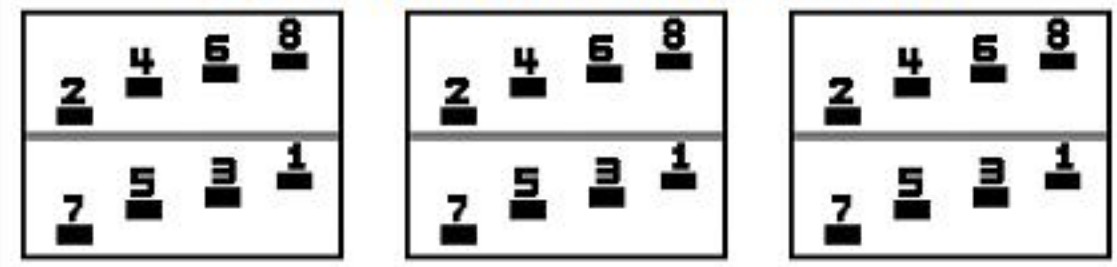

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

NET WGT
1670 LB
757.5 Kg
90226
DX77A

INSPECTION & FINAL TEST
NOG
N139!
092321



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

Note:
Outline: 303B112GEDXP77A

NEMA CLASS AA DRY TYPE TRANSFORMER Meets DOE 2016 efficiency

