



Transformer




1M0000000

Catalog Number **9T10A1183** Type **QL**


45.0 KVA 60 HZ 3 PH 3.7 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 240 VOLTS (LINE-LINE)
120 VOLTS (1 PH MIDTHAP)

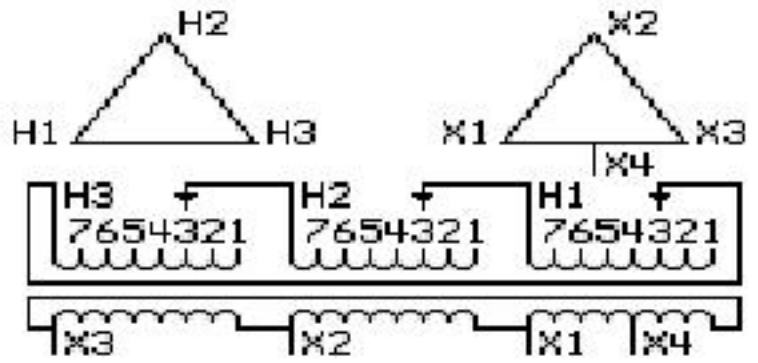

COIL TAP ARRANGEMENT

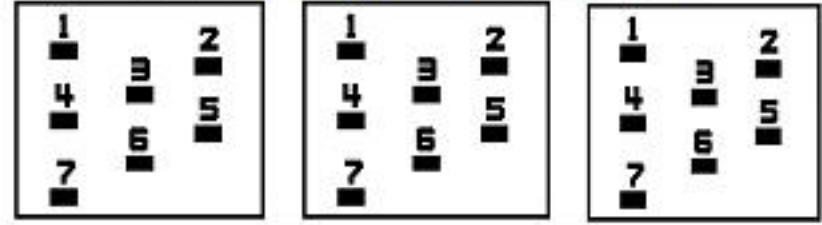

JUMPER CONNECTION	
TAP	VOLTS
1	503
2	493
3	480
4	467
5	457
6	444
7	431

NET WGT
444 LB
201.4 Kg

60436
UX73A
NOG
022516

INSPECTION
&
FINAL TEST
N609!



Assembled in Mexico

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06


REDUCED CAPACITY TAP RATED AT 5% OF 3 PH KVA
BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001 Outline:
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL 303B111GEUXP73A

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE


X3 H3 X2 H2 X1 H1 X4

Note: MID-TAP

X4
X1 H1
X1 H1
X2 H2
X2 H2
X3 H3
X3 H3
X4
X4

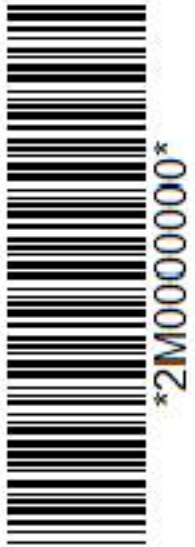

2M0000000

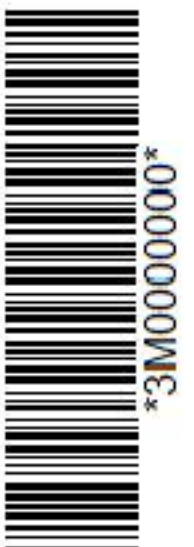

3M0000000