



Transformer

—
by ABB




1M000000

Catalog Number **Type QL**
9T10A1184


75.0 KVA 60 HZ 3 PH 5.6 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 240 VOLTS (LINE-LINE)
120 VOLTS (1 PH MIDTAP X1-X4)

JUMPER CONNECTION	
TAP	VOLTS
1	505
2	491
3	480
4	469
5	455
6	445
7	431

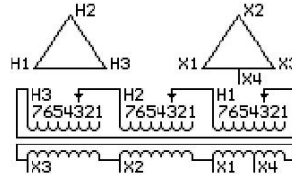

COIL TAP ARRANGEMENT

 

NET WGT	INSPECTION & FINAL TEST
561 LB	
254.5 Kg	NOG
89215	N137!
UY74A	091021



LISTED 769G

H1	-	-	-	-	-	-	-
X1	-	-	-	-	-	-	-
H2	-	-	-	-	-	-	-
X2	-	-	-	-	-	-	-
H3	-	-	-	-	-	-	-
X3	-	-	-	-	-	-	-
H4	-	-	-	-	-	-	-
X4	-	-	-	-	-	-	-



2M000000



3M000000

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

REDUCED CAPACITY TAP RATED AT 5% OF 3 PH KVA

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.

CHECK ADDITIONAL NEC AND LOCAL CODE

ASSEMBLED IN MEXICO

X4 X3 H3 X2 H2 X1 H1

Note: MID-TAP

Outline: 303B111GEUY74A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency