



# Transformer



\*1M0000000\*

Catalog Number

9T10A1185G03

Type QL

112.5 KVA 60 HZ 3 PH 4.9 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)  
SECONDARY (X) 240 VOLTS (LINE-LINE)  
120 VOLTS (1 PH MIDTHAP)

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

ENCLOSURE TYPE 2 (IP20) OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1076G06

REDUCED CAPACITY TAP RATED AT 5% OF 3 PH KVA


BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001 Outline:  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL 303B111GEDXP75A

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES  
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE


GE Energy Industrial Solutions

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

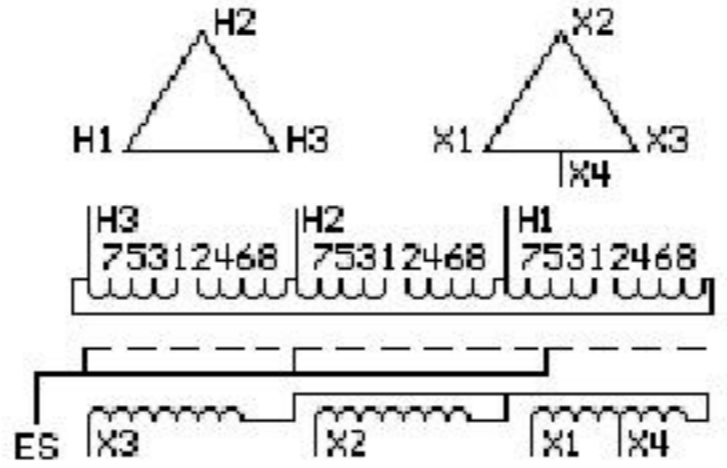

### COIL TAP ARRANGEMENT

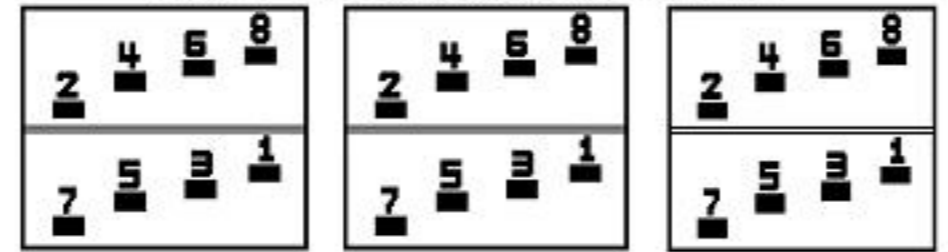

JUMPER CONNECTION	
TAP	VOLTS
1-2	502
2-3	493
3-4	480
4-5	467
5-6	458
6-7	444
7-8	431

NET WGT  
830 LB  
376.5 Kg

59160  
DX75A  
NOG  
020116

INSPECTION  
&  
FINAL TEST  
N606!



Assembled in Mexico

X3 - X2 - X1 - X4  
- H3 - H2 - H1

Note: MID-TAP

X4

-

X1

-

X2

-

X3

-

H2

-

H3

-

-

X1

-

X2

-

X3

-

H2

-

H3

-



\*2M0000000\*



\*3M0000000\*