



Transformer

by ABB



1M000000


Catalog Number 9T10A1185G31 **Type QL**

112.5 KVA 60 HZ 3 PH 5.3 % IMP
40 C AMB. 115 C RISE 220 C SYSTEM IS-19C


PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 240 VOLTS (LINE-LINE)
120 VOLTS (1 PH MIDTAP X1-X4)

JUMPER CONNECTION

TAP	VOLTS
1-2	502
2-3	493
3-4	480
4-5	467
5-6	458
6-7	444
7-8	431

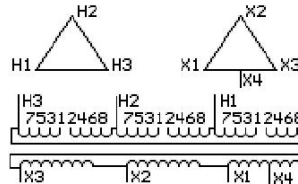

COIL TAP ARRANGEMENT

 

NET WGT 830 LB
376.5 Kg
89219 DX75A
INSPECTION & FINAL TEST
NOG N137!
091021



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1076G06

REDUCED CAPACITY TAP RATED AT 5% OF 3 PH KVA

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.

CHECK ADDITIONAL NEC AND LOCAL CODE

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

ASSEMBLED IN MEXICO

X3 - X2 - X1 - X4

- H3 - H2 - H1

Note: MID-TAP

Outline: 303B11GEDXP75A



2M000000



3M000000