



# Transformer



\*1M0000000\*


Catalog Number      Type QL

**9T10A1188**


**300.0 KVA    60 HZ    3 PH 7.5 % IMP**

40 C AMB.    150 C RISE    220 C SYSTEM    IS-19C

PRIMARY (H)    480 VOLTS (LINE-LINE)  
SECONDARY (X)    240 VOLTS (LINE-LINE)  
                          120 VOLTS (1 PH MIDTHAP)

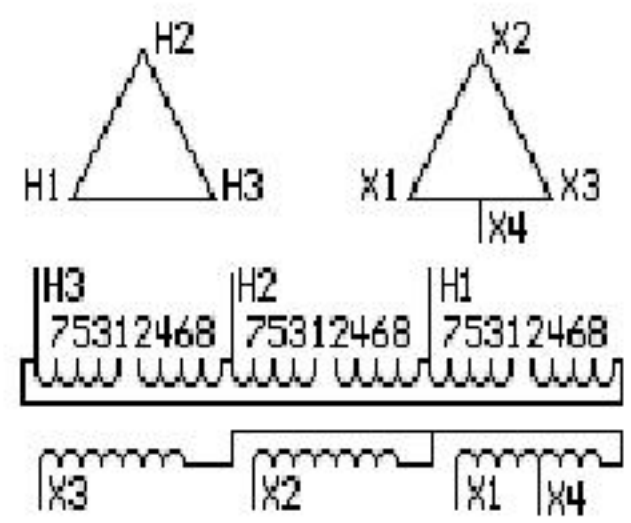

### COIL TAP ARRANGEMENT

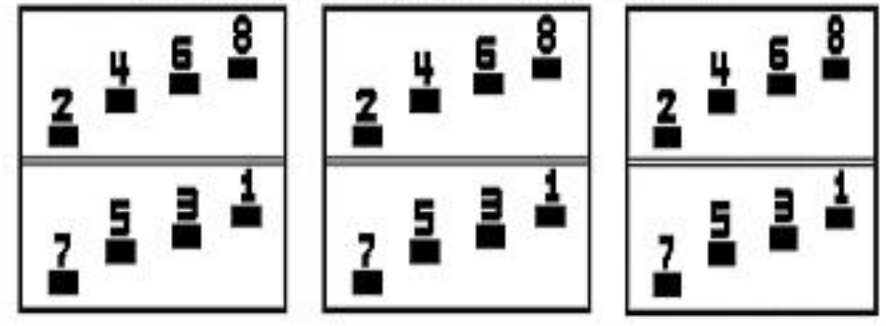

JUMPER CONNECTION	
TAP	VOLTS
1-2	504
2-3	492
3-4	480
4-5	468
5-6	456
6-7	444
7-8	432

NET WGT  
**1670 LB**  
757.5 Kg

59007  
**DY78A**  
NOG  
**011416**

INSPECTION  
&  
FINAL TEST  
**N603!**



Assembled in Mexico

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077 G06

REDUCED CAPACITY TAP RATED AT 5% OF 3 PH KVA

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001      Outline:  
ALUMINUM CONDUCTOR    PRIMARY: 10 KV BIL    SECONDARY: 10 KV BIL    303B112GEDYP78A

**IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE**

