



Transformer

by ABB




1M000000

Catalog Number 9T10A1235 **Type** QL


112.5 KVA 60 HZ 3 PH 4.8 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 400 VOLTS (LINE-LINE)

JUMPER CONNECTION	TAP VOLTS
1-2	502
2-3	494
3-4	480
4-5	468
5-6	455
6-7	443
7-8	434

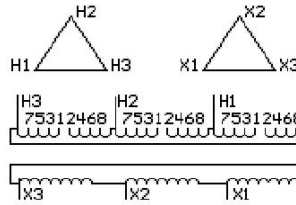

COIL TAP ARRANGEMENT

 

NET WGT	INSPECTION & FINAL TEST
680 LB	TEST
308.4 Kg	NOG
89232	N137!
DY75A	091021



LISTED 769G

X3 - X2 - X1 - H3 - H2 - H1
X3 - X2 - X1 - H3 - H2 - H1

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

ASSEMBLED IN MEXICO

X3 - X2 - X1 - -

- H3 - H2 - H1

Note: standard

Outline: 303B111GEDYP75A



2M000000



3M000000