



# Transformer

by ABB




\*1M000000\*

**Catalog Number** 9T10A1261G31 **Type** QL


15.0 KVA 60 HZ 3 PH 3.7 % IMP  
40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)  
SECONDARY (X) 230 VOLTS (LINE-LINE)

JUMPER CONNECTION TAP	VOLTS
1	504
2	491
3	480
4	468
5	456
6	443
7	433

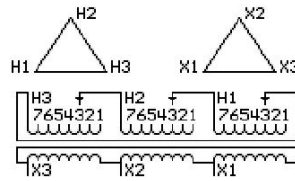

### COIL TAP ARRANGEMENT

 

**NET WGT** 231 LB  
**INSPECTION & FINAL TEST** 104.8 Kg  
**NOG** 89235  
**N139!** UX71A  
**092021**



X3 H3 X2 H2 X1 H1  
 X3 H3 X2 H2 X1 H1

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1071G06

ASSEMBLED IN MEXICO

**BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001**  
 ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL  
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.  
 CHECK ADDITIONAL NEC AND LOCAL CODE

X3 H3 X2 H2 X1 H1 -

Note: standard

Outline: 303B111GEUXP71A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

