

Transformer

—
by ABB



1M000000


Catalog Number **Type QL**
9T10A1277

225.0 KVA 60 HZ 3 PH 5.4 % IMP
 40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 480 VOLTS (LINE-LINE)
 SECONDARY (H) 575 VOLTS (LINE-LINE)
 332 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION

TAP	VOLTS
1-2	504
2-3	492
3-4	480
4-5	467
5-6	455
6-7	443
7-8	430

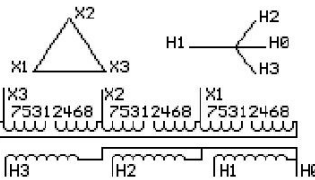

NET WGT
 1450 LB
 657.7 Kg
 89237
 DY77A

INSPECTION & FINAL TEST
 NOG
 N139!
 092021



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009
 ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B112GEDYP77A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000