



# Transformer



\*1M000000\*

Catalog Number


Type QL

9T10A1326


150.0 KVA 60 HZ 3 PH 3.9 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)  
SECONDARY (H) 240 VOLTS (LINE-LINE)  
120 VOLTS (1 PH MIDTAP)

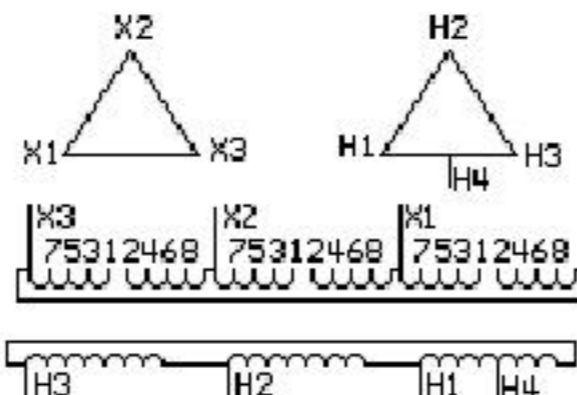

### COIL TAP ARRANGEMENT

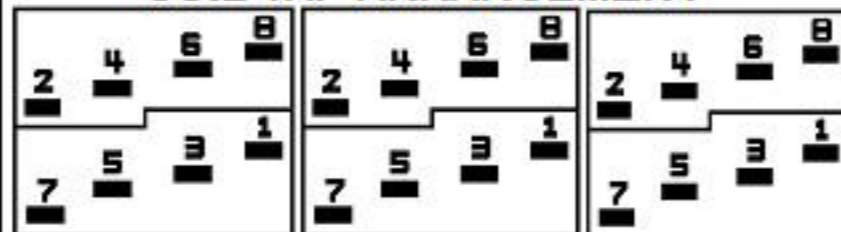

JUMPER CONNECTION	
TAP	VOLTS
1-2	219
2-3	214
3-4	208
4-5	203
5-6	198
6-7	193
7-8	188

NET WGT

1250 LB  
567.0 Kg

60569  
DK76A

NOG  
031516

INSPECTION  
&  
FINAL TEST  
N612!



LISTED 769G

Assembled in Mexico

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

REDUCED CAPACITY TAP RATED AT 5% OF 3 PH KVA

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

Outline:


ALUMINUM CONDUCTOR

PRIMARY: 10 KV BIL


SECONDARY: 10 KV BIL

303B112GEDXP76A

**IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE**

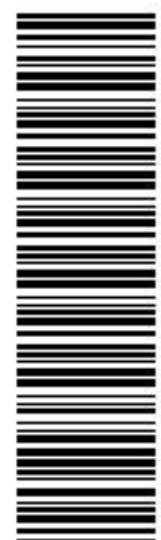

\*2M000000\*

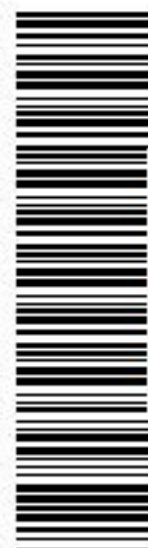

\*3M000000\*