



Transformer

by ABB



 

1M000000

Catalog Number 9T10A1327 **Type** QL

225.0 KVA 60 HZ 3 PH 4.6 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)
SECONDARY (H) 240 VOLTS (LINE-LINE)
120 VOLTS (1 PH MIDTAP H1-H4)

JUMPER CONNECTION	TAP VOLTS
1-2	221
2-3	215
3-4	208
4-5	202
5-6	196
6-7	189
7-8	183

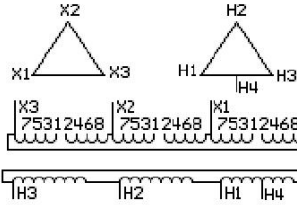

NET WGT 1670 LB 757.5 Kg	INSPECTION & FINAL TEST NOG N139! 092021
89247 DY78A	



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y107G06
REDUCED CAPACITY TAP RATED AT 5% OF 3 PH KVA

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

ASSEMBLED IN MEXICO

Note:

Outline: 303B112GEDYP78A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000