



Transformer

by ABB



1M000000


Catalog Number 9T10A1342G02

Type QL


30.0 KVA 60 HZ 3 PH 5 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)
SECONDARY (H) 480 VOLTS (LINE-LINE)
 277 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	
TAP	VOLTS
1	219
2	213
3	208
4	203
5	197
6	193
7	187

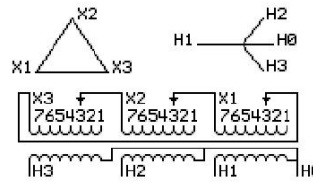

COIL TAP ARRANGEMENT

 

NET WGT
330 LB
149.7 Kg
89265
UX72A

INSPECTION & FINAL TEST
NOG
N139!
092021



Energy Verified
EV519886



LISTED 769G

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

ASSEMBLED IN MEXICO

H3 X3 H2 X2 H1 X1 H0

Note: **standard**

Outline: 303B111GEUXP72A

H3	X3	H2	X2	H1	X1	H0
2M000000						
3M000000						