



Transformer

by ABB



1M000000


Catalog Number 9T10A1344 **Type** QL

75.0 KVA 60 HZ 3 PH 5.3 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C


JUMPER CONNECTION

TAP	VOLTS
1	219
2	211
3	208
4	204
5	197

PRIMARY (X) 208 VOLTS (LINE-LINE)
 SECONDARY (H) 480 VOLTS (LINE-LINE)
 277 VOLTS (LINE-NEUTRAL)

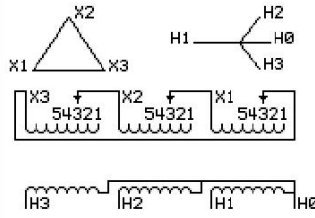

COIL TAP ARRANGEMENT

 

NET WGT
 561 LB
 254.5 Kg
 89271
 UY74A

INSPECTION & FINAL TEST
 NOG
 N139!
 092021



LISTED 769G

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

H3	X3	H2	X2	H1	X1
-	-	-	-	-	-

 
Note: H0 at the bottom

Outline: 303B111GEUYP74A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

H3 X3 H2 X2 H1 X1



2M000000

H3 X3 H2 X2 H1 X1



3M000000

H0