



Transformer

by ABB



1M000000


Catalog Number 9T10A1344 **Type** QL

75.0 KVA 60 HZ 3 PH 5.3 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C


JUMPER CONNECTION

TAP	VOLTS
1	219
2	211
3	208
4	204
5	197

PRIMARY (X) 208 VOLTS (LINE-LINE)
 SECONDARY (H) 480 VOLTS (LINE-LINE)
 277 VOLTS (LINE-NEUTRAL)

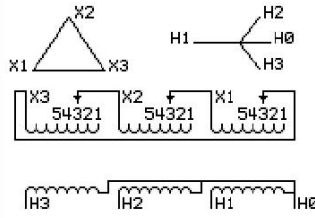

COIL TAP ARRANGEMENT

 

NET WGT
 561 LB
 254.5 Kg
 89271
 UY74A

INSPECTION & FINAL TEST
 NOG
 N137!
 091021



LISTED 769G

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

H3	X3	H2	X2	H1	X1
-	-	-	-	-	-

 
Note: H0 at the bottom

Outline: 303B111GEUY74A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

H3 X3 H2 X2 H1 X1
 H3 X3 H2 X2 H1 X1
 H3 X3 H2 X2 H1 X1



2M000000



3M000000

H0