



Transformer

by ABB



1M000000


Catalog Number 9T10A1344G05 **Type** QL

75.0 KVA 60 HZ 3 PH 6.6 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)
SECONDARY (H) 480 VOLTS (LINE-LINE)
277 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION

TAP	VOLTS
1	217
2	214
3	208
4	204
5	197

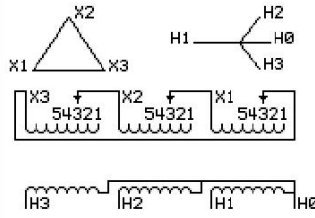


NET WGT
561 LB
254.5 Kg
89273
UY74A

INSPECTION & FINAL TEST
NOG
N137!
091021



 COIL TAP ARRANGEMENT



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

H3 X3 H2 X2 H1 X1

Note: H0 at the bottom

Outline: 303B111GEUY74A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

H3 X3 H2 X2 H1 X1
- - - - -
H3 X3 H2 X2 H1 X1
- - - - -



2M000000



3M000000

H0