



# Transformer



\*1M0000000\*

Catalog Number


**9T10A1345G31**

Type QL


**112.5 KVA 60 HZ 3 PH 2.9 % IMP**

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)  
SECONDARY (H) 480 VOLTS (LINE-LINE)  
277 VOLTS (LINE-NEUTRAL)

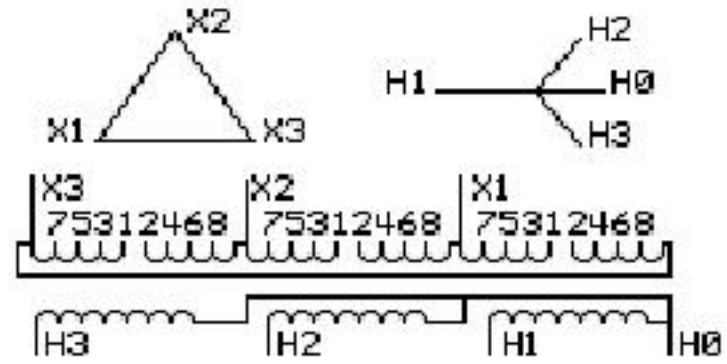

### COIL TAP ARRANGEMENT

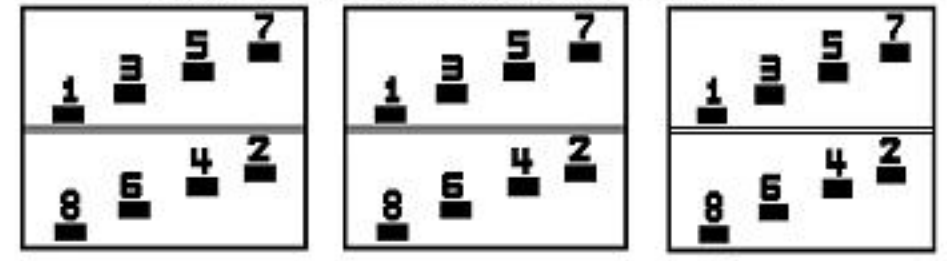

JUMPER CONNECTION	
TAP	VOLTS
1-2	219
2-3	214
3-4	208
4-5	202
5-6	196
6-7	191
7-8	185

NET WGT  
1030 LB  
467.2 Kg

58911  
DY76A

NOG  
010416

INSPECTION  
&  
FINAL TEST  
N602!



ENCLOSURE TYPE 2 (IP20) OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1076G06

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL Outline: 303B111GEDYP76A

H3 - H2 - H1 - -  
- X3 - X2 - X1

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE

Note: H0 at the bottom



\*2M0000000\*



\*3M0000000\*

H3 - H2 - H1 - -  
- X3 - X2 - X1  
H3 - H2 - H1 - -  
- X3 - X2 - X1  
H0