



Transformer

by ABB




1M000000

Catalog Number 9T10A1353 **Type** QL

45.0 KVA 60 HZ 3 PH 4.5 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)
SECONDARY (H) 380 VOLTS (LINE-LINE)
219 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	TAP VOLTS
1	219
2	213
3	208
4	202
5	199
6	193
7	187

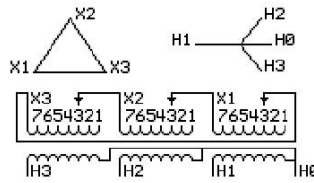


NET WGT
603 LB
273.5 Kg
89292
UX74A

INSPECTION & FINAL TEST
NOG
N139!
092021



 COIL TAP ARRANGEMENT



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

ASSEMBLED IN MEXICO

H3 X3 H2 X2 H1 X1

Note: H0 at the bottom

Outline: 303B111GEUXP74A

H3 X3 H2 X2 H1 X1
- - - - -
2M000000

H3 X3 H2 X2 H1 X1
- - - - -
3M000000

H0