



Transformer

by ABB




1M000000

Catalog Number 9T10A1354 **Type** QL

75.0 KVA 60 HZ 3 PH 3.2 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)
SECONDARY (H) 380 VOLTS (LINE-LINE)
219 VOLTS (LINE-NEUTRAL)


JUMPER CONNECTION	TAP VOLTS
1	219
2	215
3	208
4	203
5	199
6	190
7	186

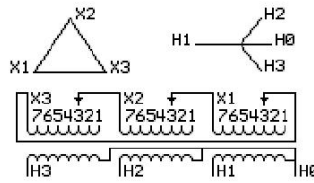

NET WGT 680 LB
308.4 Kg
89293 DY75A
INSPECTION & FINAL TEST
NOG N137!
091021



 COIL TAP ARRANGEMENT



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

ASSEMBLED IN MEXICO

H3 - H2 - H1 - -
- X3 - X2 - X1

Note: H0 at the bottom

Outline: 303B111GEDYP75A

H3 - H2 - H1 - -
- X3 - X2 - X1

H3 - H2 - H1 - -
- X3 - X2 - X1

H0

2M000000

3M000000