



Transformer

by ABB




1M000000

Catalog Number 9T10A1442 **Type** QL

30.0 KVA 60 HZ 3 PH 4.8 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)
SECONDARY (H) 220 VOLTS (LINE-LINE)
127 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	TAP VOLTS
1	218
2	212
3	208
4	202
5	198
6	193
7	187

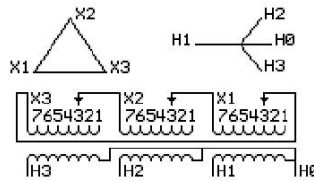


NET WGT
330 LB
149.7 Kg
89303
UX72A

INSPECTION & FINAL TEST
NOG
N139!
092021



 COIL TAP ARRANGEMENT



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

H3 X3 H2 X2 H1 X1 H0

Note: standard

Outline: 303B111GEUXP72A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

H3	X3	H2	X2	H1	X1	H0
-	-	-	-	-	-	-
2M000000						
3M000000						