



Transformer

by ABB



1M000000


Catalog Number 9T10A2184G33
Type QL

75.0 KVA 60 HZ 3 PH 6.2 % IMP
 40 C AMB. 115 C RISE 220 C SYSTEM IS-19C


JUMPER CONNECTION	TAP VOLTS
1	484
2	473
3	460
4	448
5	437
6	426
7	415

PRIMARY (H) 460 VOLTS (LINE-LINE)
 SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

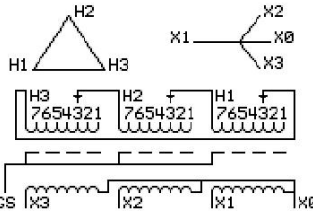

COIL TAP ARRANGEMENT

 

NET WGT 603 LB
 273.5 Kg
 89410 UOX74A
 INSPECTION & FINAL TEST NOG N139! 092021



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

X3 H3 X2 H2 X1 H1

Note: X0 at the bottom

Outline: 303B111GEUXP74A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

X3 H3 X2 H2 X1 H1
 X3 H3 X2 H2 X1 H1
 X0



2M000000



3M000000