



Transformer

—
by ABB



1M000000


Catalog Number 9T10A2386
Type QL

150.0 KVA 60 HZ 3 PH 3.7 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C


JUMPER CONNECTION
TAP VOLTS

1	629
2	618
3	600
4	583
5	572
6	554
7	543

PRIMARY (H) 600 VOLTS (LINE-LINE)
SECONDARY (X) 480 VOLTS (LINE-LINE)
277 VOLTS (LINE-NEUTRAL)

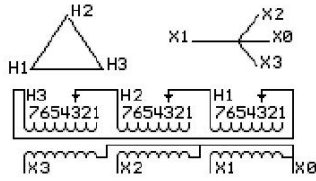

COIL TAP ARRANGEMENT

 

NET WGT
1030 LB
467.2 Kg
89436
DY76A

INSPECTION & FINAL TEST
NOG
N139!
092021



X0

- H1 - X1 -

- H2 - X2 -

- H3 - X3 -

2M000000

3M000000

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1076G06

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

ASSEMBLED IN MEXICO

X3 - X2 - X1 - -
- H3 - H2 - H1

Note: X0 at the bottom

Outline: 303B111GEDYP76A

