



# Transformer

—  
by ABB




\*1M000000\*

**Catalog Number**      **Type QL**  
**9T10A2387**


225.0 KVA    60 HZ    3 PH    4.7 % IMP  
40 C AMB.    150 C RISE    220 C SYSTEM    IS-19C

PRIMARY (H)      600 VOLTS (LINE-LINE)  
SECONDARY (X)    480 VOLTS (LINE-LINE)  
                         277 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	
TAP	VOLTS
1-2	632
2-3	612
3-4	600
4-5	586
5-6	567
6-7	554
7-8	541

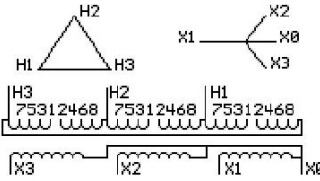

### COIL TAP ARRANGEMENT

 

<b>NET WGT</b> 1450 LB 657.7 Kg 89437 DY77A	<b>INSPECTION &amp; FINAL TEST</b> <b>NOG</b> N139! 092021
---	---



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

ASSEMBLED IN MEXICO

**BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009**  
 ALUMINUM CONDUCTOR    PRIMARY: 10 KV BIL    SECONDARY: 10 KV BIL  
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.  
 CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B112GEDYP77A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



\*2M000000\*



\*3M000000\*