



Transformer

by ABB



1M000000


Catalog Number **Type QL**
9T10A2411

15.0 KVA 60 HZ 3 PH 3.7 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C


Note: Design is based on 15.00KVA & 115C Rise 3.5% Imp.

PRIMARY (H) 600 VOLTS (LINE-LINE)
SECONDARY (X) 230 VOLTS (LINE-LINE)
 133 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	TAP VOLTS
1	630
2	615
3	600
4	586
5	569
6	554
7	540

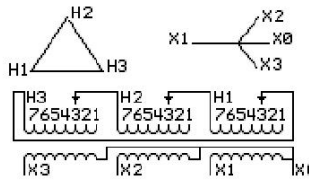

COIL TAP ARRANGEMENT

 

NET WGT
231 LB
104.8 Kg
89446
UX71A

INSPECTION & FINAL TEST
NOG
N139!
092021



LISTED 769G

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1071G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

X3	H3	X2	H2	X1	H1	X0
-	-	-	-	-	-	-

Note: standard

Outline: 303B111GEUXP71A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

X0
X1
H1
X2
H2
X3
H3



2M000000



3M000000