



Transformer

by ABB




1M000000

Catalog Number 9T10A2631 **Type** QL


15.0 KVA 60 HZ 3 PH 4.5 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 220 VOLTS (LINE-LINE)
SECONDARY (H) 600 VOLTS (LINE-LINE)

JUMPER CONNECTION TAP	VOLTS
1	232
2	226
3	220
4	214
5	208
6	204
7	198

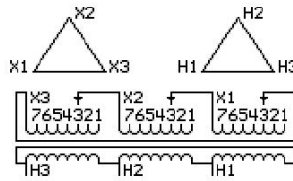

COIL TAP ARRANGMENT

 

NET WGT
231 LB
104.8 Kg
89450
UX71A

INSPECTION & FINAL TEST
NOG
N139!
092021



H3 X3 H2 X2 H1 X1 - - - - -
H3 X3 H2 X2 H1 X1 - - - - -
H3 X3 H2 X2 H1 X1 - - - - -

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1071G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

H3 X3 H2 X2 H1 X1 -

Note: standard

Outline: 303B111GEUXP71A

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

