

GE Transformer

—
by ABB




1M000000

Catalog Number **Type QL**
9T10C1004G31


75.0 KVA 60 HZ 3 PH 3.4 % IMP
40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

JUMPER CONNECTION	
TAP	VOLTS
1	503
2	494
3	480
4	467
5	458
6	445
7	431

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

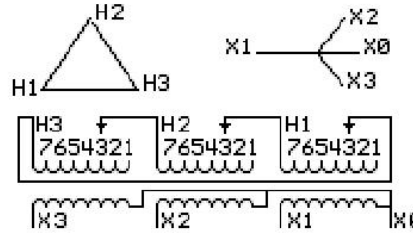

COIL TAP ARRANGEMENT

 

NET WGT **INSPECTION & FINAL TEST**
685 LB
310.7 Kg
90499 **NOG**
DX74C **N219!**
 050422



X3 H3 X2 H2 X1 H1
- - - - -
X3 H3 X2 H2 X1 H1
- - - - -
X0

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

X3 H3 X2 H2 X1 H1
- - - - -

Note: X0 at the bottom

Outline: 303B111GEDXP74C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000