



Transformer

by ABB



1M0000000

Catalog Number
9T10C1083G03

Type QL


45.0 KVA **60 HZ** **3 PH** **3.4 % IMP**
40 C AMB. **150 C RISE** **220 C SYSTEM** **IS-19C**

JUMPER CONNECTION TAP VOLTS


- 1 505
- 2 491
- 3 480
- 4 469
- 5 455
- 6 444
- 7 433

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 400 VOLTS (LINE-LINE)
231 VOLTS (LINE-NEUTRAL)

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

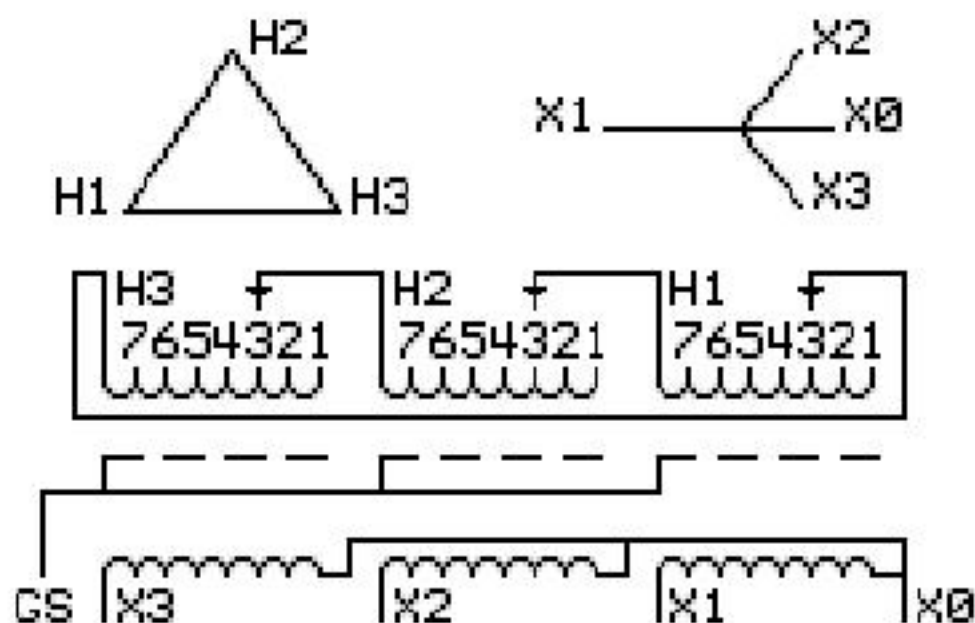

COIL TAP ARRANGEMENT

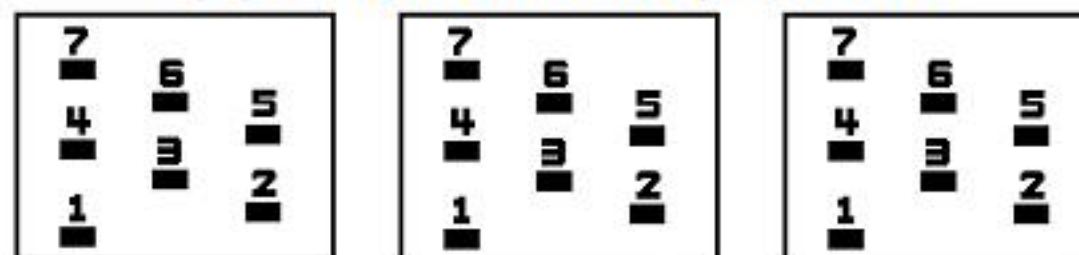

NET WGT
480 LB
217.7 Kg
88860
UX73C

INSPECTION & FINAL TEST
NOG
N137!
091021



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.

CHECK ADDITIONAL NEC AND LOCAL CODE

X3	H3	X2	H2	X1	H1	-
-	-	-	-	-	-	-

Note: X0 at the top

Outline: 303B111GEUXP73C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency