



Transformer

by ABB



1M000000

Catalog Number
9T10C1087


Type QL

225.0 KVA 60 HZ 3 PH 3.6 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C


**JUMPER
CONNECTION**

TAP	VOLTS
1-2	502
2-3	494
3-4	480
4-5	470
5-6	454
6-7	446
7-8	430

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 400 VOLTS (LINE-LINE)
231 VOLTS (LINE-NEUTRAL)

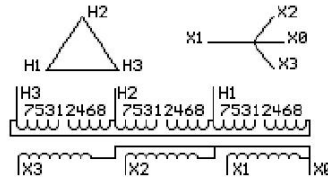

COIL TAP ARRANGEMENT

 

NET WGT
1610 LB
730.3 Kg
89596
DY77C

**INSPECTION
& FINAL
TEST**
NOG
N139!
092021



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y107G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009

COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.

CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B112GEDYP77C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000