



# Transformer

—  
by ABB




\*1M000000\*

**Catalog Number**      **Type QL**  
**9T10C1088**

300.0 KVA    60 HZ    3 PH    5.5 % IMP  
40 C AMB.    150 C RISE    220 C SYSTEM    IS-19C

**JUMPER CONNECTION**  
**TAP VOLTS**

- 1-2 502
- 2-3 494
- 3-4 480
- 4-5 470
- 5-6 454
- 6-7 446
- 7-8 430

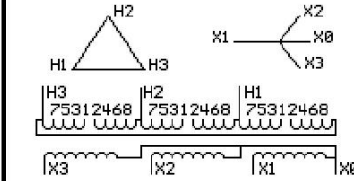


**NET WGT**  
1970 LB  
893.6 Kg  
89600  
DY78C

**INSPECTION & FINAL TEST**  
NOG  
N139!  
092021



LISTED 769G

 **PRIMARY (H)**    480 VOLTS (LINE-LINE)  
**SECONDARY (X)**    400 VOLTS (LINE-LINE)  
                                 231 VOLTS (LINE-NEUTRAL)



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

ASSEMBLED IN MEXICO

**BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009**  
COPPER CONDUCTOR    PRIMARY: 10 KV BIL    SECONDARY: 10 KV BIL  
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.  
CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B112GEDYP78C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



\*2M000000\*



\*3M000000\*