



Transformer

by ABB




1M000000

Catalog Number 9T10C1113 **Type** QL


45.0 KVA 60 HZ 3 PH 3.6 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 480 VOLTS (LINE-LINE)
SECONDARY (H) 575 VOLTS (LINE-LINE)

JUMPER CONNECTION	TAP VOLTS
1	502
2	491
3	480
4	469
5	455
6	444
7	433

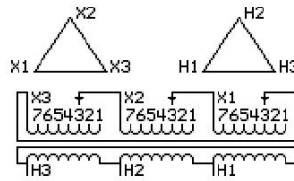

COIL TAP ARRANGEMENT

 

NET WGT	INSPECTION & FINAL TEST
480 LB	
217.7 Kg	NOG
88865	N137!
UX73C	091021



LISTED 769G

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

ASSEMBLED IN MEXICO

H3 X3 H2 X2 H1 X1 -

Note: standard

 
Outline: 303B111GEUXP73C

H3 X3 H2 X2 H1 X1



2M000000

H3 X3 H2 X2 H1 X1



3M000000