



1M000000


Catalog Number 9T10C1173G31 **Type** QL

45.0 KVA 60 HZ 3 PH 3.1 % IMP
40 C AMB. 115 C RISE 220 C SYSTEM IS-19C


JUMPER CONNECTION
TAP VOLTS

- | | |
|---|-----|
| 1 | 505 |
| 2 | 490 |
| 3 | 480 |
| 4 | 469 |
| 5 | 455 |
| 6 | 444 |
| 7 | 433 |

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 480 VOLTS (LINE-LINE)
 277 VOLTS (LINE-NEUTRAL)

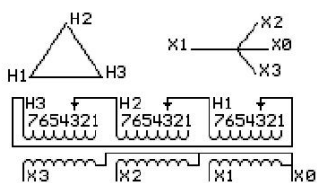

COIL TAP ARRANGMENT

 

NET WGT INSPECTION & FINAL TEST
480 LB TEST
217.7 Kg NOG
88870 N137!
UX73C 091021



X3 H3 X2 H2 X1 H1 -
X3 H3 X2 H2 X1 H1 -
X3 H3 X2 H2 X1 H1 -
X0

ENCLOSURE TYPE 2 (IP20). OR RAINTYPE TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

X3 H3 X2 H2 X1 H1 -

Note: X0 at the top

Outline: 303B111GEUXP73C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000