



Transformer

by ABB



1M000000


Catalog Number **Type QL**
9T10C1178

300.0 KVA **60 HZ** **3 PH** **5 % IMP**
40 C AMB. **150 C RISE** **220 C SYSTEM** **IS-19C**


PRIMARY (H) **480 VOLTS (LINE-LINE)**
SECONDARY (X) **480 VOLTS (LINE-LINE)**
 277 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION

TAP	VOLTS
1-2	505
2-3	489
3-4	480
4-5	465
5-6	456
6-7	440
7-8	432

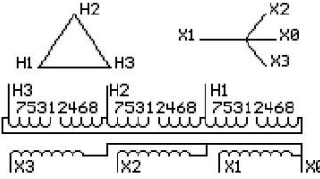

COIL TAP ARRANGEMENT

 

NET WGT **INSPECTION & FINAL TEST**
1970 LB
893.6 Kg
89645 **NOG**
DY78C **N139!**
 092021



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009
COPPER CONDUCTOR **PRIMARY: 10 KV BIL** **SECONDARY: 10 KV BIL**
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B112GEDYP78C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000