



Transformer

—
by ABB




1M000000

Catalog Number **Type QL**
9T10C1198


300.0 KVA 60 HZ 3 PH 4.4 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 240 VOLTS (LINE-LINE)

| JUMPER CONNECTION | |
|-------------------|-------|
| TAP | VOLTS |
| 1-2 | 504 |
| 2-3 | 496 |
| 3-4 | 480 |
| 4-5 | 464 |
| 5-6 | 456 |
| 6-7 | 448 |
| 7-8 | 432 |

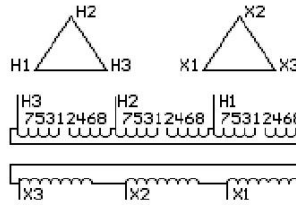

COIL TAP ARRANGMENT

 

| | |
|----------------|-------------------------|
| NET WGT | INSPECTION & FINAL TEST |
| 1970 LB | NOG |
| 893.6 Kg | N139! |
| 89687 | 092021 |
| DY78C | |



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B112GEDYP78C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000